



## ★ GLE45-XL-KRR-B

Radial insert ball bearing


Schaeffler ID:  
0008530110000

★ Preferred product

Radial insert ball bearings GLE..-KRR-B, spherical outer ring, non-locating bearing, drive slot in inner ring, R seals on both sides

X-life

### Technical information

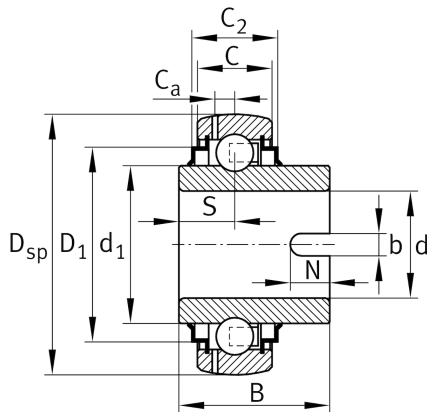

### Main Dimensions & Performance Data

d	45 mm	Bore diameter
D <sub>SP</sub>	85 mm	Outside diameter
B	42,9 mm	Width
n <sub>G Grease</sub>	9.600 1/min	Limiting speed for grease lubrication
C <sub>r</sub>	32.500 N	Basic dynamic load rating, radial
C <sub>0r</sub>	20.400 N	Basic static load rating, radial
C <sub>ur</sub>	1.060 N	Fatigue load limit, radial
	0,64 kg	Weight

### Dimensions

C	22 mm	Width, outer ring
C <sub>2</sub>	26,4 mm	Sealing total width
S	17,4 mm	Distance raceway
d <sub>1</sub>	57,9 mm	Rib diameter inner ring
D <sub>1</sub>	72,3 mm	Outside diameter seal
C <sub>a</sub>	6,4 mm	Distance to lubrication hole
N	9 mm	Hight retaining slot
b	7 mm	Width retaining slot
	H11	Width retaining slot clearance

### Additional information

f <sub>0</sub>	14,1	Calculation factor
----------------	------	--------------------