



IMAGE  
COMING SOON




## GRA103-NPP-B-AS2/V

Radial insert ball bearing

Schaeffler ID:  
0502720550000

Radial insert ball bearing GRA...NPP-B-  
AS2/V

### Technical information

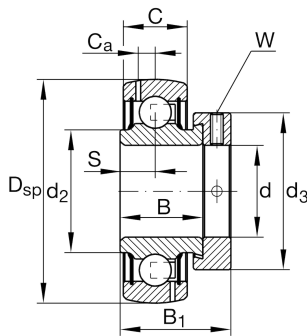

#### Main Dimensions & Performance Data

d	30,162 mm	Bore diameter
d	1.1875 inch	Bore diameter, inch
D <sub>SP</sub>	62 mm	Outside diameter
B <sub>1</sub>	35,8 mm	Locking collar total width
B	23,8 mm	Width
C <sub>ur</sub>	590 N	Fatigue load limit, radial
C <sub>r</sub>	20.700 N	Basic dynamic load rating, radial
C <sub>0r</sub>	11.300 N	Basic static load rating, radial
	0,003 kg	Weight

#### Dimensions

C	18 mm	Width, outer ring
S	9 mm	Distance raceway
d <sub>2</sub>	37,3 mm	Rib diameter sealing inner ring
C <sub>a</sub>	4,9 mm	Distance to lubrication hole
d <sub>3</sub>	44 mm	Outside diameter locking collar/locknut
W	0.15625 inch	Width across flats (Inch)

#### Calculation factors

f <sub>0</sub>	13,8	Calculation factor
----------------	------	--------------------