

RAE40-XL-NPP-FA106


Radial insert ball bearing

Schaeffler ID:
0008432290000

Radial insert ball bearing RAE...-XL-NPP

X-life

Technical information

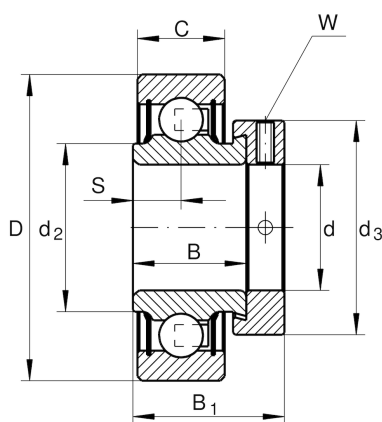

Main Dimensions & Performance Data

d	40 mm	Bore diameter
D	80 mm	Outside diameter
B	30,2 mm	Width
B ₁	43,8 mm	Locking collar total width
C _r	32.500 N	Basic dynamic load rating, radial
C _{0r}	19.800 N	Basic static load rating, radial
C _{ur}	1.030 N	Fatigue load limit, radial
	0,606 kg	Weight

Dimensions

C	21 mm	Width, outer ring
S	11 mm	Distance raceway
d ₂	49,4 mm	Rib diameter sealing inner ring
d ₃	58 mm	Outside diameter locking collar/locknut
W	5 mm	Width of flats

Calculation factors

f ₀	13,6	Calculation factor
----------------	------	--------------------