



★ RAE35-XL-NPP-B

Radial insert ball bearing


Schaeffler ID:
0008499600000

Radial insert ball bearing RAE...XL-NPP-B

★ Preferred product

X-life

Technical information

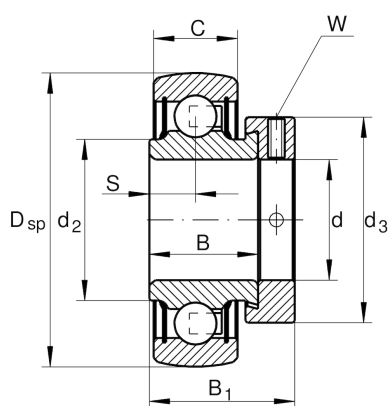

Main Dimensions & Performance Data

d	35 mm	Bore diameter
D _{SP}	72 mm	Outside diameter
B	25,4 mm	Width
B ₁	39 mm	Locking collar total width
n _{G Grease}	11.700 1/min	Limiting speed for grease lubrication
C _r	25.500 N	Basic dynamic load rating, radial
C _{0r}	15.300 N	Basic static load rating, radial
C _{ur}	650 N	Fatigue load limit, radial
	0,52 kg	Weight

Dimensions

C	19 mm	Width, outer ring
S	9,5 mm	Distance raceway
d ₂	44,6 mm	Rib diameter sealing inner ring
d ₃	55 mm	Outside diameter locking collar/locknut
W	5 mm	Width of flats

Additional information

f ₀	13,8	Calculation factor
----------------	------	--------------------