



IMAGE
COMING SOON



PCJT30-XL-N-FA125



Flanged housing unit

Schaeffler ID:
0096281180000

Housing units PCJT...FA125, two-bolt
flanged housing units, cast iron, eccentric
locking collar, P seals, with anti-corrosion
protection

X-life

Technical information

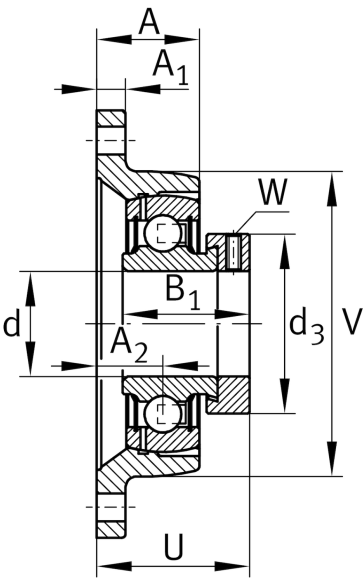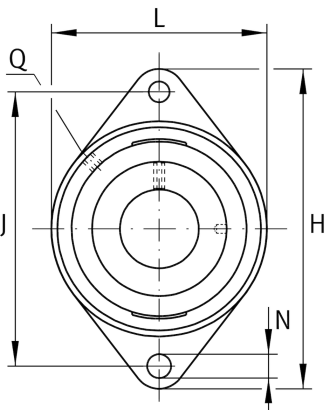

Main Dimensions & Performance Data

d	30 mm	Bore diameter
L	80 mm	Flange width
H	142 mm	Height flange
U	46,8 mm	Total height unit
C _r	20.700 N	Basic dynamic load rating, radial
C _{0r}	11.300 N	Basic static load rating, radial
C _{ur}	480 N	Fatigue load limit, radial
	0,84 kg	Weight

Dimensions

A	29 mm	Height housing
	1	Number of housings
A ₁	12 mm	Thickness of flange
A ₂	20 mm	Distance raceway
	CJT06	Housing
	GRAE30-XL-NPP-B-FA125	Bearing designation
	KASK06	Protecting cap
V	80 mm	Shoulder diameter housing
Q	Rp1/8	Connection thread lubrication
d ₃	44 mm	Outside diameter eccentric locking collar

Mounting dimensions

J	116,5 mm	Distance fixing bore
N	11.5 mm	Fixing bore
n	2	Number of screwing holes