



PCJT35-XL-N-FA125


Flanged housing unit

Schaeffler ID:
0096286570000

Housing units PCJT..-FA125, two-bolt
flanged housing units, cast iron, eccentric
locking collar, P seals, with anti-corrosion
protection

X-life

Technical information

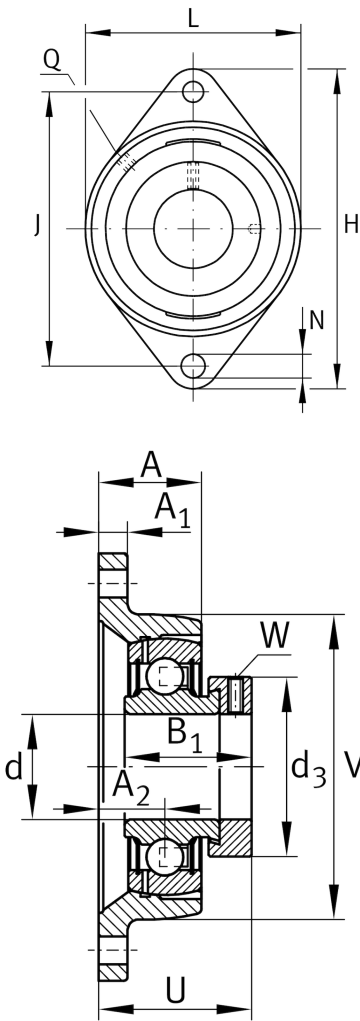

Main Dimensions & Performance Data

d	35 mm	Bore diameter
L	92 mm	Flange width
H	155 mm	Height flange
U	50,5 mm	Total height unit
C _r	27.500 N	Basic dynamic load rating, radial
C _{0r}	15.300 N	Basic static load rating, radial
C _{ur}	650 N	Fatigue load limit, radial
	1,18 kg	Weight

Dimensions

A	30,5 mm	Height housing
1		Number of housings
A ₁	12,5 mm	Thickness of flange
A ₂	21 mm	Distance raceway
	CJT07	Housing
	GRAE35-XL-NPP-B-FA125	Bearing designation
	KASK07	Protecting cap
V	92 mm	Shoulder diameter housing
Q	M6	Connection thread lubrication
d ₃	55 mm	Outside diameter eccentric locking collar

Mounting dimensions

J	130 mm	Distance fixing bore
N	14 mm	Fixing bore
n	2	Number of screwing holes