

## ★ RASEY25-XL-N

Plummer block housing unit


Schaeffler ID:  
0008582930000

Plummer block housing units RASEY, cast iron housing, radial insert ball bearing with grub screws in inner ring, R seals

★ Preferred product

X-life

### Technical information

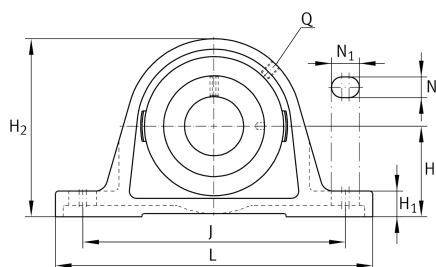

#### Main Dimensions & Performance Data

d	25 mm	Bore diameter
L	130 mm	Length total
H <sub>2</sub>	70 mm	Height
	0,7 kg	Weight

#### Dimensions

H	36,5 mm	Distance shaft axis
A	36 mm	Width (base)
A <sub>1</sub>	21 mm	Width (head)
H <sub>1</sub>	14,5 mm	Height (base)
Q	Rp1/8	Connection thread lubrication

#### Mounting dimensions

J	102,5 mm	Distance fixing bore
N	11 mm	Width (slot)
N <sub>1</sub>	19 mm	Length (slot)

#### Additional information

ASE05	Housing
GYE25-XL-KRR-B	Bearing designation
KASK05	Protecting cap

