



## ★ RASEY50-XL-N

Plummer block housing unit


Schaeffler ID:  
0008583230000

Plummer block housing units RASEY, cast iron housing, radial insert ball bearing with grub screws in inner ring, R seals

★ Preferred product

X-life

### Technical information

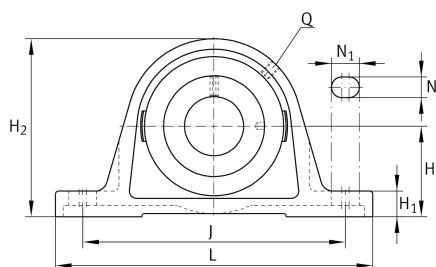

#### Main Dimensions & Performance Data

d	50 mm	Bore diameter
L	200 mm	Length total
H <sub>2</sub>	115 mm	Height
	2,62 kg	Weight

#### Dimensions

H	57,2 mm	Distance shaft axis
A	54 mm	Width (base)
A <sub>1</sub>	34 mm	Width (head)
H <sub>1</sub>	21,5 mm	Height (base)
Q	Rp1/8	Connection thread lubrication

#### Mounting dimensions

J	158 mm	Distance fixing bore
N	18 mm	Width (slot)
N <sub>1</sub>	23 mm	Length (slot)

#### Additional information

ASE10	Housing
GYE50-XL-KRR-B	Bearing designation
KASK10	Protecting cap

