



★ RASEY60-XL-N

Plummer block housing unit


Schaeffler ID:
0009477680000

Plummer block housing units RASEY, cast iron housing, radial insert ball bearing with grub screws in inner ring, R seals

★ Preferred product

X-life

Technical information

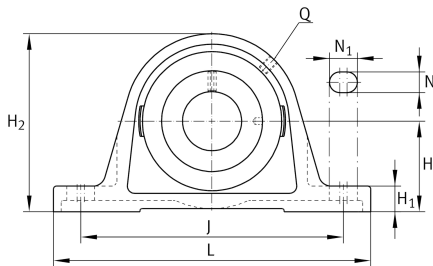

Main Dimensions & Performance Data

d	60 mm	Bore diameter
L	240 mm	Length total
H ₂	140 mm	Height
	4,44 kg	Weight

Dimensions

H	69,9 mm	Distance shaft axis
A	60 mm	Width (base)
A ₁	42 mm	Width (head)
H ₁	25 mm	Height (base)
Q	Rp1/8	Connection thread lubrication

Mounting dimensions

J	190 mm	Distance fixing bore
N	18 mm	Width (slot)
N ₁	28 mm	Length (slot)

Additional information

ASE12	Housing
GYE60-XL-KRR-B	Bearing designation
KASK12	Protecting cap

