





## PHE40-TV-FA125.5

Take-up housing unit

Schaeffler ID:  
0574652070000

Take-up housing unit PHE..-TV, RIBB  
plastic

### Technical information

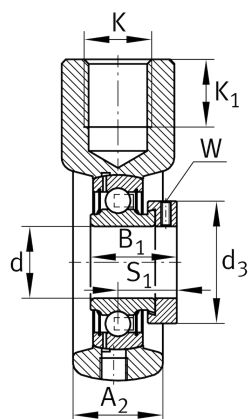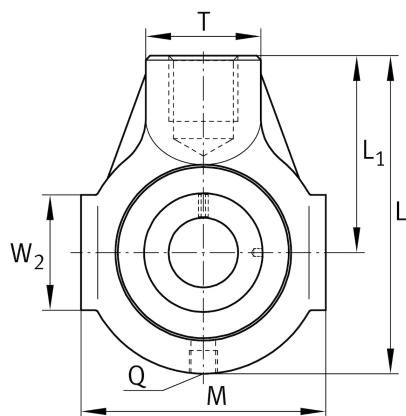

### Main Dimensions & Performance Data

d	40 mm	Bore diameter
L	140 mm	Length
M	100 mm	Housing total width
	1,02 kg	Weight

### Dimensions

T	40 mm	Height (housing, mounting side)
	HE08-TV	Housing
	GRAE40-NPP-B-	Bearing designation
	FA107/125.5	
A <sub>2</sub>	34,5 mm	Width housing
	KASK08-S-G	End cap
	KASK08-S-R-NBR	Open protecting cap

### Mounting dimensions

L <sub>1</sub>	85 mm	Distance shaft axis
L <sub>3</sub>	80 mm	Length guidance grooves
K	M16	Thread fixing bore
Q	1/4-28 UNF	Connection thread lubrication