

## ★ KR19


### Yoke type track roller

Schaeffler ID:  
0000310890000

Stud type track rollers KR, with axial guidance, gap seals on both sides

★ Preferred product

## Technical information

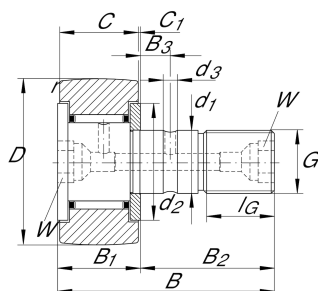

### Main Dimensions & Performance Data

D	19 mm	Outside diameter
d <sub>1</sub>	8 mm	Fit diameter of roller stud / stud
B	32 mm	Width
C <sub>r w</sub>	3.500 N	Basic dynamic load rating, radial
C <sub>0r w</sub>	4.050 N	Basic static load rating, radial
C <sub>ur w</sub>	550 N	Fatigue load limit, radial
n <sub>D G</sub>	11.000 1/min	Speed on permanent grease lubrication
	39,52 g	Weight

### Dimensions

B <sub>1</sub>	12,2 mm	Maximum width of thrust washer
B <sub>2</sub>	20 mm	Bolt/stud length effectively
C	11 mm	Width, outer ring
C <sub>1</sub>	0,6 mm	Protrusion outer ring to thrust washer
r <sub>min</sub>	0,15 mm	Minimum chamfer dimension
d <sub>2</sub>	15 mm	Stop diameter of thrust washer
G	M8	Thread
l <sub>G</sub>	10 mm	Thread length
R	500 mm	Radius of outer ring outside profile

### Additional information

	NIPA1	Drive-fit lubrication nipple
	1,5 mm	Protrusion lubrication nipple
M <sub>A</sub>	8 Nm	Tightening torque nut