

★ LR200-X-2RSR


Track roller

Schaeffler ID:
0578792060000

Track roller LR...-2RSR, single row, no plastic tyre

★ Preferred product

Technical information

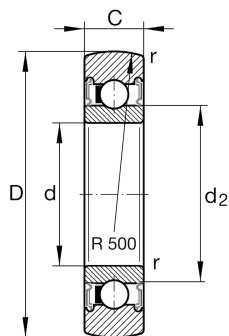

Main Dimensions & Performance Data

D	32 mm	Outside diameter
d	10 mm	Bore diameter
C	9 mm	Height
$C_{r w}$	5.100 N	Basic dynamic load rating, radial
$C_{0r w}$	2.380 N	Basic static load rating, radial
$C_{ur w}$	120 N	Fatigue load limit, radial
n_{DG}	13.000 1/min	Speed on permanent grease lubrication
	0,05 kg	Weight

Dimensions

d_2	16,6 mm	Diameter of thrust washer
r_{min}	0,6 mm	Minimum chamfer dimension
R	500 mm	Radius of outer ring outside profile