


## LR201-X-2RSR

Track roller

Schaeffler ID:  
0899650860000

Track roller LR..-2RSR, single row, no plastic tyre

### Technical information

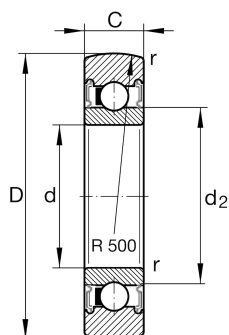

#### Main Dimensions & Performance Data

D	35 mm	Outside diameter
d	12 mm	Bore diameter
C	10 mm	Height
$C_{r w}$	6.000 N	Basic dynamic load rating, radial
$C_{0r w}$	2.850 N	Basic static load rating, radial
$C_{ur w}$	143 N	Fatigue load limit, radial
$n_{DG}$	12.000 1/min	Speed on permanent grease lubrication
	0,047 kg	Weight

#### Dimensions

$d_2$	18,3 mm	Diameter of thrust washer
$r_{min}$	0,6 mm	Minimum chamfer dimension
R	500 mm	Radius of outer ring outside profile