

★ LR204-2RSR


Track roller

Schaeffler ID:
0922432230000

Track roller LR...-2RSR, single row, no plastic tyre

★ Preferred product

Technical information

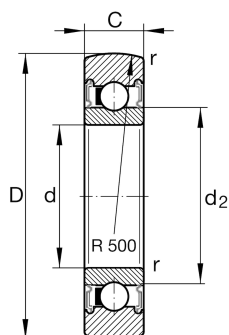

Main Dimensions & Performance Data

D	52 mm	Outside diameter
d	20 mm	Bore diameter
C	14 mm	Height
$C_{r w}$	11.300 N	Basic dynamic load rating, radial
$C_{0r w}$	5.900 N	Basic static load rating, radial
$C_{ur w}$	300 N	Fatigue load limit, radial
n_{DG}	8.000 1/min	Speed on permanent grease lubrication
	0,143 kg	Weight

Dimensions

d_2	29 mm	Diameter of thrust washer
r_{min}	1 mm	Minimum chamfer dimension
R	500 mm	Radius of outer ring outside profile