


## LR206-2RS

Track roller

Schaeffler ID:  
0008118070000

Track roller LR..-2RSR, single row, no plastic tyre

### Technical information

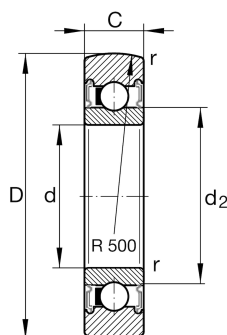

#### Main Dimensions & Performance Data

D	72 mm	Outside diameter
d	30 mm	Bore diameter
C	16 mm	Height
$C_{r w}$	17.600 N	Basic dynamic load rating, radial
$C_{0r w}$	9.900 N	Basic static load rating, radial
$C_{ur w}$	510 N	Fatigue load limit, radial
$n_{DG}$	5.500 1/min	Speed on permanent grease lubrication
	0,33 kg	Weight

#### Dimensions

$d_2$	37,4 mm	Diameter of thrust washer
$r_{min}$	1 mm	Minimum chamfer dimension
R	500 mm	Radius of outer ring outside profile