


LR207-X-2RS

Track roller

Schaeffler ID:
0008134860000

Track roller LR..-2RSR, single row, no plastic tyre

Technical information

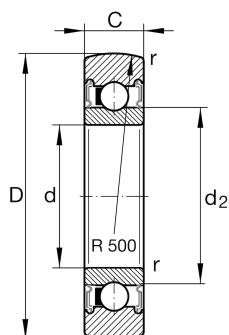

Main Dimensions & Performance Data

D	80 mm	Outside diameter
d	35 mm	Bore diameter
C	17 mm	Height
$C_{r w}$	21.900 N	Basic dynamic load rating, radial
$C_{0r w}$	12.400 N	Basic static load rating, radial
$C_{ur w}$	660 N	Fatigue load limit, radial
n_{DG}	4.500 1/min	Speed on permanent grease lubrication
	0,4 kg	Weight

Dimensions

d_2	42,4 mm	Diameter of thrust washer
r_{min}	1,1 mm	Minimum chamfer dimension
R	500 mm	Radius of outer ring outside profile