


NA2208-2RSR

Yoke type track roller

Schaeffler ID:
0000277580000

Yoke type track rollers NA22...-2RSR,
without axial guidance, lip seals on both
sides

Technical information

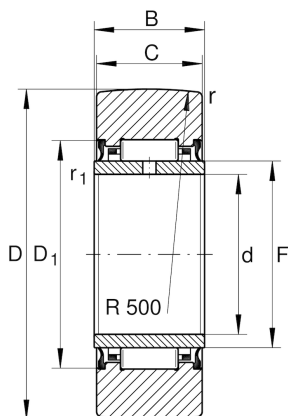

Main Dimensions & Performance Data

D	80 mm	Outside diameter
F	48 mm	Raceway diameter inner ring
C	22,7 mm	Width, outer ring
$C_{r w}$	26.000 N	Basic dynamic load rating, radial
$C_{0r w}$	41.500 N	Basic static load rating, radial
$C_{ur w}$	5.400 N	Fatigue load limit, radial
n_{DG}	850 1/min	Speed on permanent grease lubrication
	0,486 kg	Weight

Dimensions

d	40 mm	Bore diameter
B	23 mm	Width, inner ring
$D_{1 \min}$	57 mm	Minimum mounting dimension
r_{\min}	1,1 mm	Minimum chamfer dimension
$r_{1 \min}$	0,6 mm	Minimum chamfer dimension
R	500 mm	Radius of outer ring outside profile