

★ NATV25


Yoke type track roller

Schaeffler ID:
0000344950000

★ Preferred product

Yoke type track rollers NATV, full complement needle roller set, with axial guidance, gap seals on both sides

Technical information

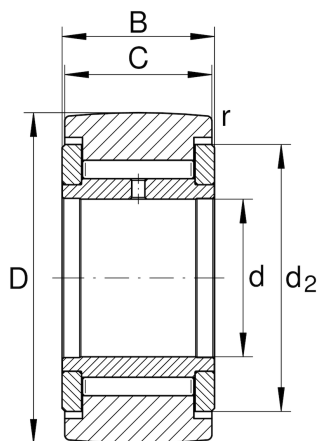

Main Dimensions & Performance Data

d	25 mm	Bore diameter
D	52 mm	Outside diameter
B	25 mm	Width, inner ring
$C_{r w}$	20.200 N	Basic dynamic load rating, radial
$C_{0r w}$	44.500 N	Basic static load rating, radial
$C_{ur w}$	6.300 N	Fatigue load limit, radial
n_{DG}	1.000 1/min	Speed on permanent grease lubrication
$F_{0r per}$	44.500 N	Permissible static load, radial
$F_{r per}$	43.500 N	Permissible dynamic load outer ring, radial
	0,003 kg	Weight

Dimensions

C	24 mm	Width, outer ring
d_2	41,5 mm	Outside diameter of thrust washer
r_{min}	1 mm	Minimum chamfer dimension
R	500 mm	Radius of outer ring outside profile