



## ★ RNA22/6-2RSR


Yoke type track roller

Schaeffler ID:  
0000271540000

Yoke type track rollers RNA22...-2RSR,  
without axial guidance, lip seals on both  
sides

★ Preferred product

### Technical information

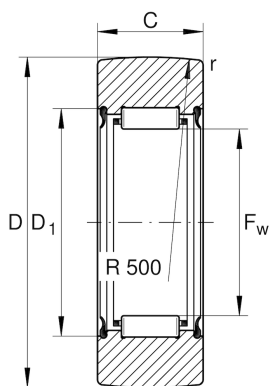

### Main Dimensions & Performance Data

D	19 mm	Outside diameter
F <sub>w</sub>	10 mm	Under roller diameter
C	11,8 mm	Width, outer ring
C <sub>rw</sub>	3.900 N	Basic dynamic load rating, radial
C <sub>orw</sub>	3.700 N	Basic static load rating, radial
C <sub>urw</sub>	495 N	Fatigue load limit, radial
n <sub>DG</sub>	9.000 1/min	Speed on permanent grease lubrication
	13,905 g	Weight

### Dimensions

D <sub>1 min</sub>	15,15 mm	Minimum mounting dimension
r <sub>min</sub>	0,3 mm	Minimum chamfer dimension
R	500 mm	Radius of outer ring outside profile