


RNA2201-2RSR

Yoke type track roller

Schaeffler ID:
0000272190000

Yoke type track rollers RNA22...-2RSR,
without axial guidance, lip seals on both
sides

Technical information

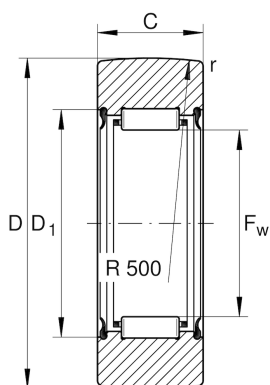

Main Dimensions & Performance Data

D	32 mm	Outside diameter
F _w	16 mm	Under roller diameter
C	13,8 mm	Width, outer ring
C _{r w}	7.500 N	Basic dynamic load rating, radial
C _{0r w}	8.300 N	Basic static load rating, radial
C _{ur w}	1.290 N	Fatigue load limit, radial
n _{D G}	4.700 1/min	Speed on permanent grease lubrication
	56,55 g	Weight

Dimensions

D _{1 min}	22 mm	Minimum mounting dimension
r _{min}	0,6 mm	Minimum chamfer dimension
R	500 mm	Radius of outer ring outside profile