

★ RNA2202-2RSR


Yoke type track roller

Schaeffler ID:
0000272350000

★ Preferred product

Yoke type track rollers RNA22...-2RSR,
without axial guidance, lip seals on both
sides

Technical information

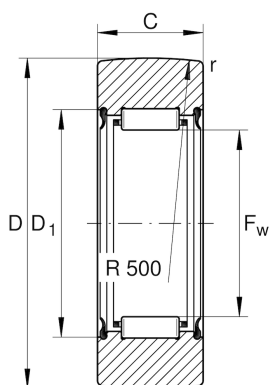

Main Dimensions & Performance Data

D	35 mm	Outside diameter
F_w	20 mm	Under roller diameter
C	13,8 mm	Width, outer ring
$C_{r w}$	7.600 N	Basic dynamic load rating, radial
$C_{0r w}$	9.900 N	Basic static load rating, radial
$C_{ur w}$	1.390 N	Fatigue load limit, radial
n_{DG}	3.400 1/min	Speed on permanent grease lubrication
	60 g	Weight

Dimensions

$D_{1 \min}$	26 mm	Minimum mounting dimension
r_{\min}	0,6 mm	Minimum chamfer dimension
R	500 mm	Radius of outer ring outside profile