


RNA2203-2RSR

Yoke type track roller

Schaeffler ID:
0000272510000

Yoke type track rollers RNA22...-2RSR,
without axial guidance, lip seals on both
sides

Technical information

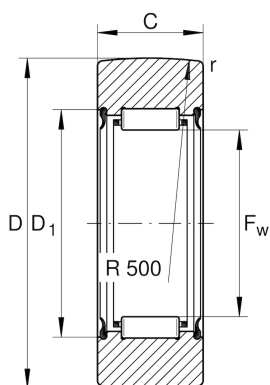

Main Dimensions & Performance Data

D	40 mm	Outside diameter
F _w	22 mm	Under roller diameter
C	15,8 mm	Width, outer ring
C _{r w}	9.900 N	Basic dynamic load rating, radial
C _{0r w}	14.200 N	Basic static load rating, radial
C _{ur w}	1.870 N	Fatigue load limit, radial
n _{D G}	3.000 1/min	Speed on permanent grease lubrication
	94,61 g	Weight

Dimensions

D _{1 min}	28 mm	Minimum mounting dimension
r _{min}	1 mm	Minimum chamfer dimension
R	500 mm	Radius of outer ring outside profile