


## RNA2204-2RSR

Yoke type track roller

Schaeffler ID:  
0007031840000

Yoke type track rollers RNA22...-2RSR,  
without axial guidance, lip seals on both  
sides

### Technical information

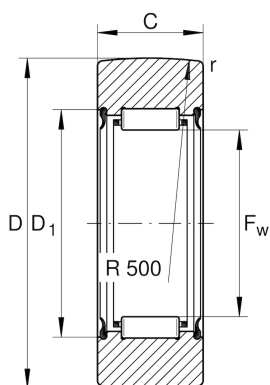

#### Main Dimensions & Performance Data

D	47 mm	Outside diameter
F <sub>w</sub>	25 mm	Under roller diameter
C	17,8 mm	Width, outer ring
C <sub>r w</sub>	14.000 N	Basic dynamic load rating, radial
C <sub>0r w</sub>	19.300 N	Basic static load rating, radial
C <sub>ur w</sub>	2.700 N	Fatigue load limit, radial
n <sub>D G</sub>	2.300 1/min	Speed on permanent grease lubrication
	0,146 kg	Weight

#### Dimensions

D <sub>1 min</sub>	33 mm	Minimum mounting dimension
r <sub>min</sub>	1 mm	Minimum chamfer dimension
R	500 mm	Radius of outer ring outside profile