



## ★ RSTO12


Yoke type track roller

Schaeffler ID:  
0000542400000

Yoke type track rollers RSTO, without axial guidance, outer ring without ribs

★ Preferred product

### Technical information

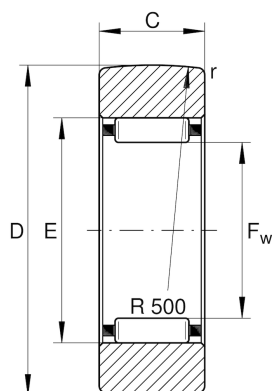

### Main Dimensions & Performance Data

D	32 mm	Outside diameter
F <sub>w</sub>	16 mm	Under roller diameter
C	11,8 mm	Width, outer ring
C <sub>r w</sub>	9.000 N	Basic dynamic load rating, radial
C <sub>0r w</sub>	10.400 N	Basic static load rating, radial
C <sub>ur w</sub>	1.560 N	Fatigue load limit, radial
n <sub>DG</sub>	4.500 1/min	Speed on permanent grease lubrication
	47,71 g	Weight

### Dimensions

E	22 mm	Raceway diameter outer ring
r <sub>min</sub>	0,3 mm	Minimum chamfer dimension
R	500 mm	Radius of outer ring outside profile