

★ RSTO15


Yoke type track roller

Schaeffler ID:
0000542590000

Yoke type track rollers RSTO, without axial guidance, outer ring without ribs

★ Preferred product

Technical information

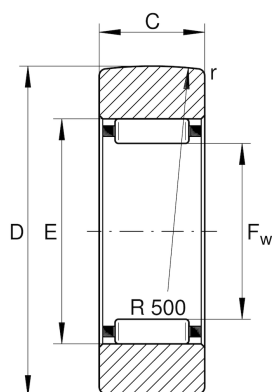

Main Dimensions & Performance Data

D	35 mm	Outside diameter
F_w	20 mm	Under roller diameter
C	11,8 mm	Width, outer ring
$C_{r w}$	9.100 N	Basic dynamic load rating, radial
$C_{0r w}$	11.100 N	Basic static load rating, radial
$C_{ur w}$	1.670 N	Fatigue load limit, radial
n_{DG}	3.300 1/min	Speed on permanent grease lubrication
	0,051 kg	Weight

Dimensions

E	26 mm	Raceway diameter outer ring
r_{min}	0,3 mm	Minimum chamfer dimension
R	500 mm	Radius of outer ring outside profile