


## RSTO17

Yoke type track roller

Schaeffler ID:  
0000542670000

Yoke type track rollers RSTO, without axial guidance, outer ring without ribs

### Technical information

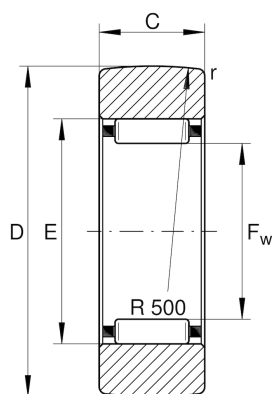

#### Main Dimensions & Performance Data

D	40 mm	Outside diameter
F <sub>w</sub>	22 mm	Under roller diameter
C	15,8 mm	Width, outer ring
C <sub>r w</sub>	14.200 N	Basic dynamic load rating, radial
C <sub>0r w</sub>	18.200 N	Basic static load rating, radial
C <sub>ur w</sub>	2.550 N	Fatigue load limit, radial
n <sub>DG</sub>	2.800 1/min	Speed on permanent grease lubrication
	93,85 g	Weight

#### Dimensions

E	29 mm	Raceway diameter outer ring
r <sub>min</sub>	0,3 mm	Minimum chamfer dimension
R	500 mm	Radius of outer ring outside profile