


RSTO35

Yoke type track roller

Schaeffler ID:
0000543130000

Yoke type track rollers RSTO, without axial guidance, outer ring without ribs

Technical information

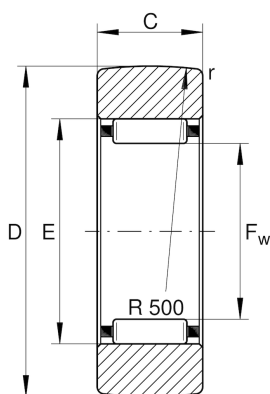

Main Dimensions & Performance Data

D	72 mm	Outside diameter
F _w	42 mm	Under roller diameter
C	19,8 mm	Width, outer ring
C _{r w}	25.000 N	Basic dynamic load rating, radial
C _{0r w}	41.000 N	Basic static load rating, radial
C _{ur w}	5.500 N	Fatigue load limit, radial
n _{DG}	1.100 1/min	Speed on permanent grease lubrication
	0,004 kg	Weight

Dimensions

E	50 mm	Raceway diameter outer ring
r _{min}	0,6 mm	Minimum chamfer dimension
R	500 mm	Radius of outer ring outside profile