

## ★ RSTO6-TV


Yoke type track roller

Schaeffler ID:  
0001621910000

Yoke type track rollers RSTO, without axial guidance, outer ring without ribs

★ Preferred product

### Technical information

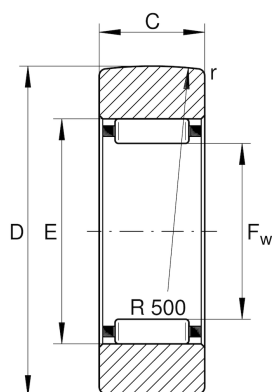

#### Main Dimensions & Performance Data

D	19 mm	Outside diameter
$F_w$	10 mm	Under roller diameter
C	9,8 mm	Width, outer ring
$C_{r w}$	3.750 N	Basic dynamic load rating, radial
$C_{0r w}$	4.600 N	Basic static load rating, radial
$C_{ur w}$	660 N	Fatigue load limit, radial
$n_{DG}$	10.000 1/min	Speed on permanent grease lubrication
	12,96 g	Weight

#### Dimensions

E	13 mm	Raceway diameter outer ring
$r_{min}$	0,3 mm	Minimum chamfer dimension
R	500 mm	Radius of outer ring outside profile