

★ RSTO8-TV


Yoke type track roller

Schaeffler ID:
0002640830000

Yoke type track rollers RSTO, without axial guidance, outer ring without ribs

★ Preferred product

Technical information

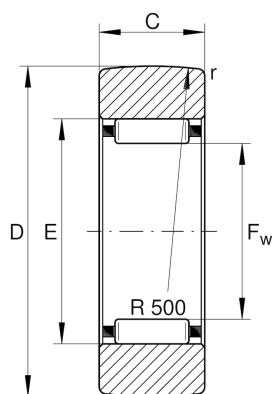

Main Dimensions & Performance Data

D	24 mm	Outside diameter
F_w	12 mm	Under roller diameter
C	9,8 mm	Width, outer ring
$C_{r w}$	4.200 N	Basic dynamic load rating, radial
$C_{0r w}$	5.600 N	Basic static load rating, radial
$C_{ur w}$	800 N	Fatigue load limit, radial
n_{DG}	8.000 1/min	Speed on permanent grease lubrication
	23 g	Weight

Dimensions

E	15 mm	Raceway diameter outer ring
r_{min}	0,3 mm	Minimum chamfer dimension
R	500 mm	Radius of outer ring outside profile