

## ★ STO17


Yoke type track roller

Schaeffler ID:  
0000541190000

Yoke type track rollers STO, without axial guidance, outer ring without ribs

★ Preferred product

### Technical information

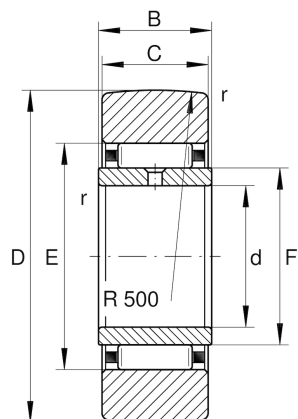

### Main Dimensions & Performance Data

d	17 mm	Bore diameter
D	40 mm	Outside diameter
C	15,8 mm	Width, outer ring
$C_{r w}$	14.200 N	Basic dynamic load rating, radial
$C_{0r w}$	18.200 N	Basic static load rating, radial
$C_{ur w}$	2.550 N	Fatigue load limit, radial
$n_{DG}$	2.800 1/min	Speed on permanent grease lubrication
	0,001 kg	Weight

### Dimensions

B	16 mm	Width, inner ring
E	29 mm	Raceway diameter outer ring
$r_{min}$	0,3 mm	Minimum chamfer dimension
F	22 mm	Raceway diameter inner ring
R	500 mm	Radius of outer ring outside profile