

★ STO25


Yoke type track roller

Schaeffler ID:
0000541350000

Yoke type track rollers STO, without axial guidance, outer ring without ribs

★ Preferred product

Technical information

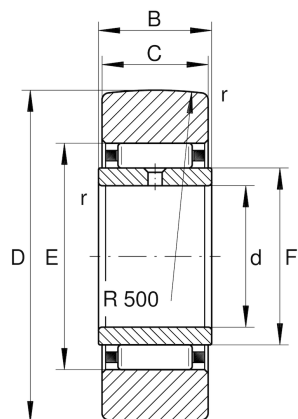

Main Dimensions & Performance Data

d	25 mm	Bore diameter
D	52 mm	Outside diameter
C	15,8 mm	Width, outer ring
$C_{r w}$	16.400 N	Basic dynamic load rating, radial
$C_{0r w}$	23.500 N	Basic static load rating, radial
$C_{ur w}$	3.350 N	Fatigue load limit, radial
n_{DG}	1.800 1/min	Speed on permanent grease lubrication
	0,002 kg	Weight

Dimensions

B	16 mm	Width, inner ring
E	37 mm	Raceway diameter outer ring
r_{min}	0,3 mm	Minimum chamfer dimension
F	30 mm	Raceway diameter inner ring
R	500 mm	Radius of outer ring outside profile