

## ★ KH14-PP



Linear ball bearing

Schaeffler ID:  
0001915310000

★ Preferred product

Linear ball bearings with initial greasing,  
sealed on both sides, with relubrication  
facility

### Technical information

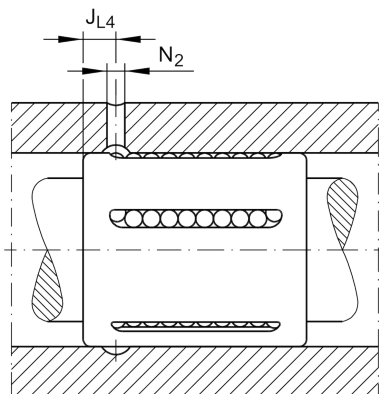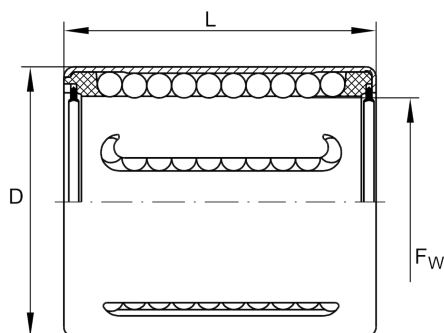

### Main Dimensions & Performance Data

$F_w$	14 mm	Diameter shaft
D	21 mm	Outer diameter
L	28 mm	Länge
$C_{min}$	690 N	load capacity dyn.
$C_{0min}$	520 N	load capacity stat.
$C_{max}$	830 N	load capacity dyn.
$C_{0max}$	760 N	load capacity stat.
	20,355 g	Weight

### Mounting dimensions

$J_{L4}$	6 mm
$N_2$	2,5 mm

### Additional information

VMKB_065	KH	Material name
----------	----	---------------