

★ KH50-PP



Linear ball bearing

Schaeffler ID:
0001939760000

★ Preferred product

Linear ball bearings with initial greasing,
sealed on both sides, with relubrication
facility

Technical information

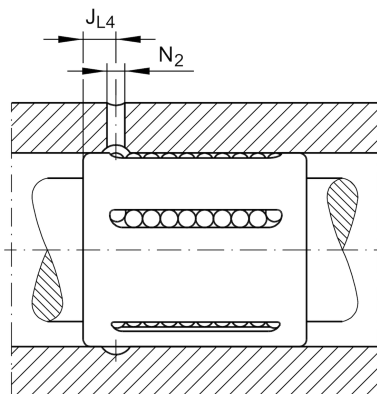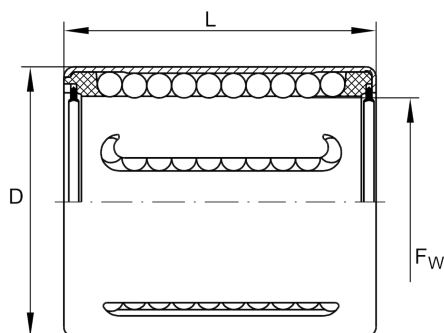

Main Dimensions & Performance Data

F_w	50 mm	Diameter shaft
D	62 mm	Outer diameter
L	70 mm	Länge
C_{min}	6.800 N	load capacity dyn.
C_{0min}	6.300 N	load capacity stat.
C_{max}	6.800 N	load capacity dyn.
C_{0max}	7.000 N	load capacity stat.
	0,003 kg	Weight

Mounting dimensions

J_{L4}	9 mm
N_2	2,5 mm

Additional information

VMKB_065	KH	Material name
----------	----	---------------