


KN20-B-PP

Linear ball bearing

Schaeffler ID:
0193187150000

Linear ball bearings KN...-B-PP, Lightweight range, closed design, sealed on all sides, with relubrication facility, adjustable angle

Technical information

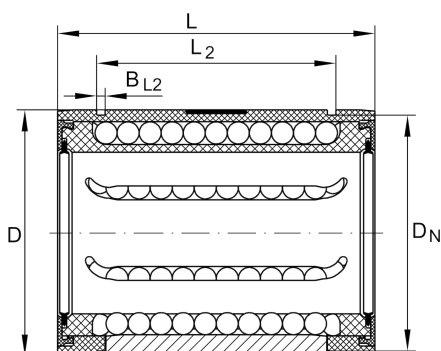

Main Dimensions & Performance Data

F_w	20 mm	Bore diameter of ball complement
D	32 mm	Outside diameter
L	45 mm	length
C_{min}	1.730 N	load capacity dyn.
C_{0min}	1.230 N	load capacity stat.
C_{max}	1.830 N	load capacity dyn.
C_{0max}	1.570 N	load capacity stat.
	60 g	Weight

Mounting dimensions

L_2	31,2 mm	
B_{L2}	1,6 mm	
D_N	30,7 mm	
T_4	0,9 mm	
N_4	3 mm	
b_{1max}	2,5 mm	
	6	Number of rows balls

