



KNO12-B-PP

Linear ball bearing

Schaeffler ID:
0244529980000

Linear ball bearings KNO..-B-PP,
Lightweight range, open design, sealed
on all sides, with relubrication facility,
adjustable angle

Technical information

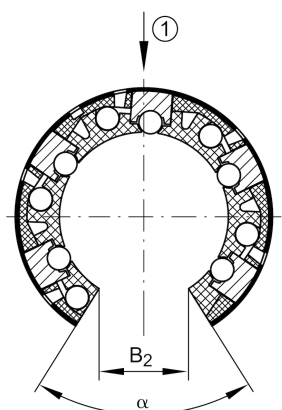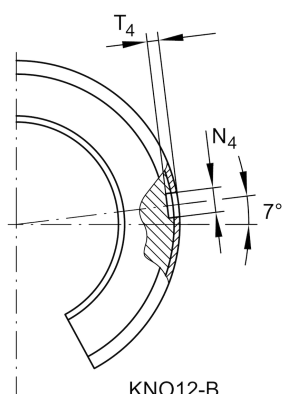

Main Dimensions & Performance Data

F_w	12 mm	Bore diameter of ball complement
D	22 mm	Outside diameter
L	32 mm	length
C_{max}	840 N	load capacity dyn.
C_{0max}	640 N	load capacity stat.
	20 g	Weight

Mounting dimensions

B_2	6,5 mm	Width of ball complement
T_4	0,7 mm	
N_4	3 mm	
α	66 °	Angle of sector opening
b_{1max}	1,5 mm	
	4	Number of rows balls

