



KNO25-B-PP

Linear ball bearing

Schaeffler ID:
0173768070000

Linear ball bearings KNO...-B-PP,
Lightweight range, open design, sealed
on all sides, with relubrication facility,
adjustable angle

Technical information

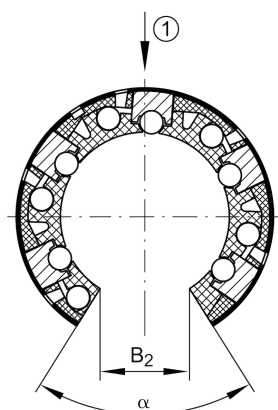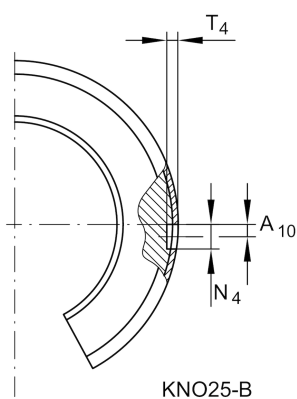

Main Dimensions & Performance Data

F_w	25 mm	Bore diameter of ball complement
D	40 mm	Outside diameter
L	58 mm	length
C_{max}	3.100 N	load capacity dyn.
C_{0max}	2.260 N	load capacity stat.
	0,113 kg	Weight

Mounting dimensions

B_2	11,5 mm	Width of sector opening
T_4	1,4 mm	
A_{10}	1,5 mm	Angle of sector opening
N_4	3 mm	
α	57 °	Angle of sector opening
b_{1max}	2,5 mm	
	5	Number of rows balls

