



## KNO40-B-PP

### Linear ball bearing

Schaeffler ID:  
0244575400000

Linear ball bearings KNO..-B-PP,  
Lightweight range, open design, sealed  
on all sides, with relubrication facility,  
adjustable angle

### Technical information

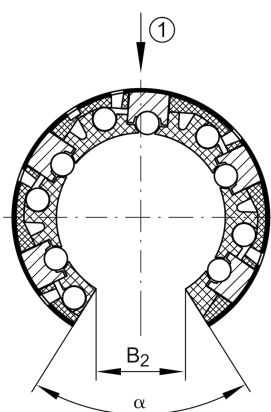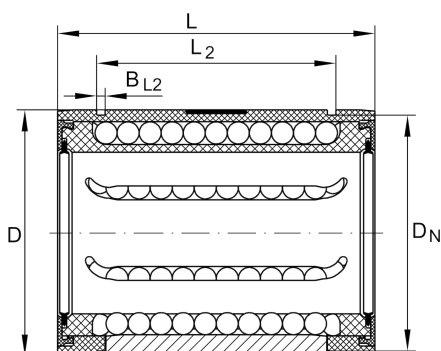

### Main Dimensions & Performance Data

$F_w$	40 mm	Bore diameter of ball complement
$D$	62 mm	Outside diameter
$L$	80 mm	length
$C_{max}$	6.300 N	load capacity dyn.
$C_{0max}$	4.350 N	load capacity stat.
	0,3 kg	Weight

### Mounting dimensions

$B_2$	19 mm	Width of sector opening
$T_4$	2,2 mm	
$A_{10}$	1,5 mm	Angle of sector opening
$N_4$	3 mm	
$\alpha$	56 °	Angle of sector opening
$b_{1max}$	3 mm	
	5	Number of rows balls

