



KNO50-B-PP

Linear ball bearing

Schaeffler ID:
0244584060000

Linear ball bearings KNO..-B-PP,
Lightweight range, open design, sealed
on all sides, with relubrication facility,
adjustable angle

Technical information

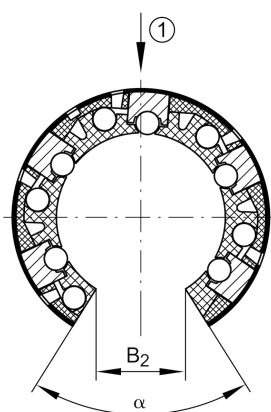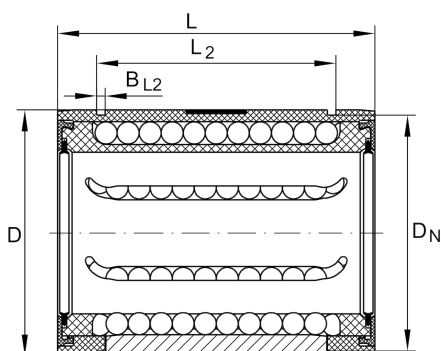

Main Dimensions & Performance Data

F_w	50 mm	Bore diameter of ball complement
D	75 mm	Outside diameter
L	100 mm	length
C_{max}	9.300 N	load capacity dyn.
C_{0max}	6.500 N	load capacity stat.
	0,554 kg	Weight

Mounting dimensions

B_2	22,5 mm	Width of sector opening
T_4	2,3 mm	
A_{10}	2,5 mm	Angle of sector opening
N_4	5 mm	
α	54 °	Angle of sector opening
b_{1max}	3 mm	
	5	Number of rows balls

