


KSO50-PP

Linear ball bearing

Schaeffler ID:
0067538410000

Linear ball bearings KSO...-PP, heavy load range, lip seals on both sides

Technical information


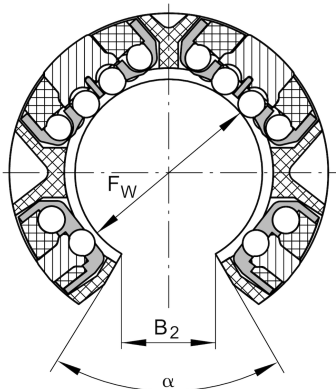



Main Dimensions & Performance Data

F_w	50 mm	Bore diameter of ball complement
D	75 mm	Outside diameter
L	100 mm	length
C_{max}	15.100 N	load capacity dyn.
C_{0max}	13.900 N	load capacity stat.
	0,47 kg	Weight

Mounting dimensions

B_2	22,7 mm	Width of sector opening
A_{10}	2,5 mm	Angle of sector opening
N_1	4,5 mm	
N_4	5 mm	
α	54 °	Angle of sector opening
	6	Number of rows balls

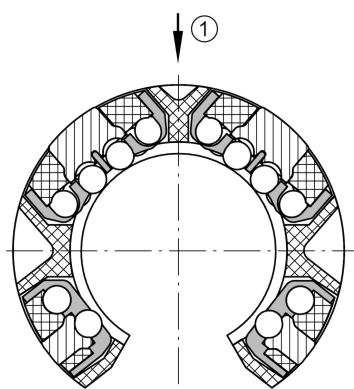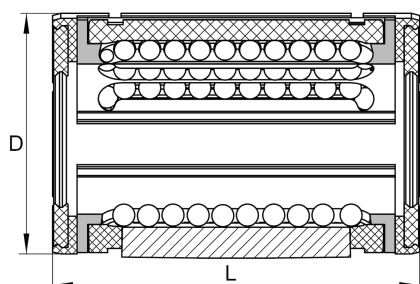

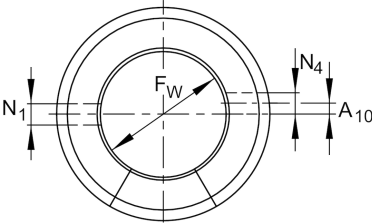

KS30, 40, 50
KSO30, 40, 50

