



207-XL-KRR-AH03


Deep groove ball bearing

Schaeffler ID:
0008127810000

Radial insert ball bearings 2..-KRR,
cylindrical outer ring, inner ring for fit, R
seals on both sides

X-life

Technical information

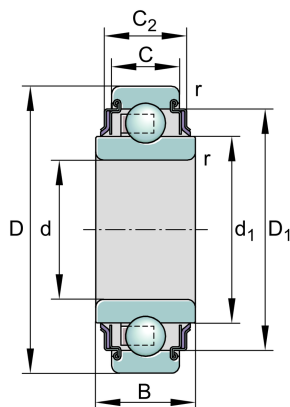

Main Dimensions & Performance Data

d	35 mm	Bore diameter
D	72 mm	Outside diameter
B	25 mm	Width
C_r	25.500 N	Basic dynamic load rating, radial
C_{0r}	15.300 N	Basic static load rating, radial
$n_{G \text{ Grease}}$	11.700 1/min	Limiting speed for grease lubrication
	0,35 kg	Weight

Dimensions

D_1	60,3 mm	Outside diameter seal
C	17 mm	Width, outer ring
C_2	19,7 mm	Sealing total width
d_1	46,8 mm	Rib diameter inner ring

Calculation factors

f_0	13,8	Calculation factor
-------	------	--------------------