



★ RABRB40/85-XL-FA106

Radial insert ball bearing


Schaeffler ID:
0009753110000

★ Preferred product

Radial insert ball bearings RABR, with rubber interliner, location by eccentric locking collar, P seals on both sides

X-life

Technical information

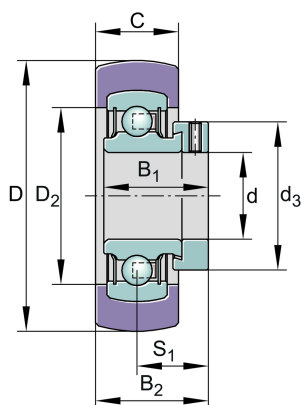

Main Dimensions & Performance Data

d	40 mm	Bore diameter
D	85 mm	Outside diameter
C	27 mm	Width, outer ring
B ₂	46,3 mm	Width total
B ₁	43,8 mm	Locking collar total width
C _r	34.500 N	Basic dynamic load rating, radial
C _{0r}	19.800 N	Basic static load rating, radial
C _{ur}	1.030 N	Fatigue load limit, radial
	3.500	Load carrying capacity (rubber interliner)
	0,652 kg	Weight

Dimensions

S ₁	32,7 mm	Distance raceway to locking collar
D ₂	70 mm	Flange diameter rubber interliner
d ₃	58 mm	Outside diameter locking collar/locknut

Additional information

	RAE40-XL-NPP-B-	Bearing designation
	FA106	
f ₀	13,6	Calculation factor
Shore A	70 °	Hardness rubber interliner