



★ RABRB12/47-XL-FA106

Radial insert ball bearing


Schaeffler ID:
0009809350000

★ Preferred product

Radial insert ball bearings RABR, with rubber interliner, location by eccentric locking collar, P seals on both sides

X-life

Technical information

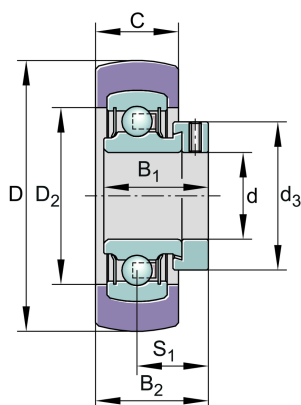

Main Dimensions & Performance Data

d	12 mm	Bore diameter
D	47,3 mm	Outside diameter
C	17,6 mm	Width, outer ring
B ₂	30,9 mm	Width total
B ₁	28,6 mm	Locking collar total width
C _r	9.800 N	Basic dynamic load rating, radial
C _{0r}	4.750 N	Basic static load rating, radial
C _{ur}	248 N	Fatigue load limit, radial
	840	Load carrying capacity (rubber interliner)
	0,16 kg	Weight

Dimensions

S ₁	22,1 mm	Distance raceway to locking collar
D ₂	33,5 mm	Flange diameter rubber interliner
d ₃	28,4 mm	Outside diameter locking collar/locknut

Additional information

	RAE12-XL-NPP-B-	Bearing designation
	FA106	
f ₀	13	Calculation factor
Shore A	70 °	Hardness rubber interliner