



★ K12X17X13-TV


Needle roller cage assembly

Schaeffler ID:
0005758606063

Needle roller cage assembly K...-TV, single
row

★ Preferred product

Technical information

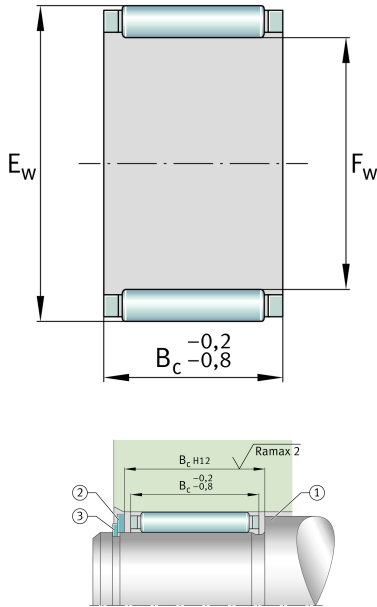

Temperature range

T_{\min}	-20 °C	Operating temperature min.
T_{\max}	120 °C	Operating temperature max.
	5,2 g	Weight

Main Dimensions & Performance Data

F_w	12 mm	Inner diameter of needle roller complement
E_w	17 mm	Outside diameter of needle roller complement
B_c	13 mm	Width
C_r	9.600 N	Basic dynamic load rating, radial
C_{0r}	10.400 N	Basic static load rating, radial
C_{ur}	1.350 N	Fatigue load limit, radial
n_G	26.500 1/min	Limiting speed
n_{gr}	18.800 1/min	Reference speed