

★ K22X32X24



Needle roller cage assembly

Schaeffler ID:
0002423496063

Needle roller cage assembly K, single row

★ Preferred product

Technical information

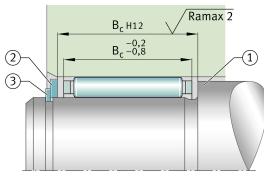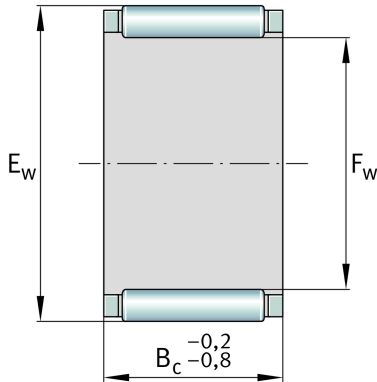

Temperature range

T_{min}	-30 °C	Operating temperature min.
T_{max}	140 °C	Operating temperature max.
	43,28 g	Weight

Main Dimensions & Performance Data

F_w	22 mm	Inner diameter of needle roller complement
E_w	32 mm	Outside diameter of needle roller complement
B_c	24 mm	Width
C_r	34.000 N	Basic dynamic load rating, radial
C_{0r}	40.000 N	Basic static load rating, radial
C_{ur}	5.000 N	Fatigue load limit, radial
n_G	18.100 1/min	Limiting speed
n_{gr}	9.700 1/min	Reference speed