

## ★ K5X8X10-TV



### Needle roller cage assembly

Schaeffler ID:  
0000297776063

Needle roller cage assembly K...-TV, single row

★ Preferred product

## Technical information

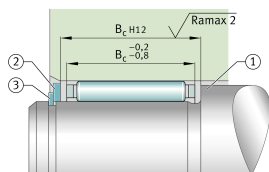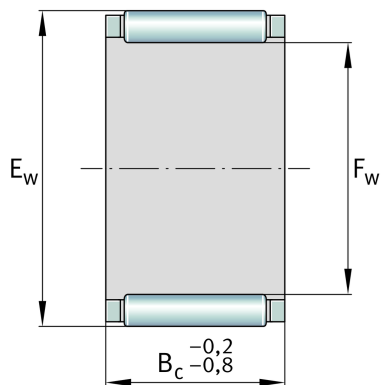

### Temperature range

$T_{min}$	-20 °C	Operating temperature min.
$T_{max}$	120 °C	Operating temperature max.
	0,88 g	Weight

### Main Dimensions & Performance Data

$F_w$	5 mm	Inner diameter of needle roller complement
$E_w$	8 mm	Outside diameter of needle roller complement
$B_c$	10 mm	Width
$C_r$	3.000 N	Basic dynamic load rating, radial
$C_{0r}$	2.650 N	Basic static load rating, radial
$C_{ur}$	360 N	Fatigue load limit, radial
$n_G$	39.000 1/min	Limiting speed
$n_{gr}$	47.000 1/min	Reference speed