



★ K6X9X8-TV


Needle roller cage assembly

Schaeffler ID:
0000239306063

Needle roller cage assembly K...-TV, single row

★ Preferred product

Technical information

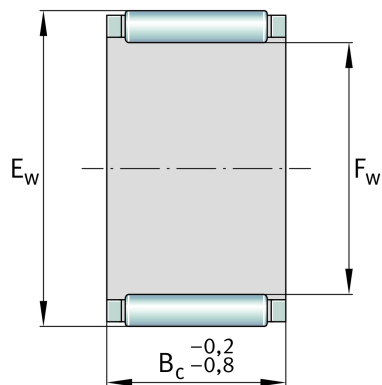

Temperature range

T_{min}	-20 °C	Operating temperature min.
T_{max}	120 °C	Operating temperature max.
	0,007 kg	Weight

Main Dimensions & Performance Data

F_w	6 mm	Inner diameter of needle roller complement
E_w	9 mm	Outside diameter of needle roller complement
B_c	8 mm	Width
C_r	2.600 N	Basic dynamic load rating, radial
C_{0r}	2.280 N	Basic static load rating, radial
C_{ur}	290 N	Fatigue load limit, radial
n_G	36.500 1/min	Limiting speed
n_{gr}	41.000 1/min	Reference speed