

## ★ K8X12X10-TV



### Needle roller cage assembly

Schaeffler ID:  
0005758286063

Needle roller cage assembly K...-TV, single row

★ Preferred product

## Technical information

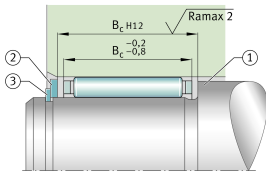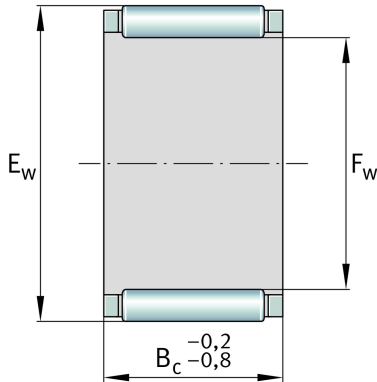

### Temperature range

$T_{min}$	-20 °C	Operating temperature min.
$T_{max}$	120 °C	Operating temperature max.
	2 g	Weight

### Main Dimensions & Performance Data

$F_w$	8 mm	Inner diameter of needle roller complement
$E_w$	12 mm	Outside diameter of needle roller complement
$B_c$	10 mm	Width
$C_r$	5.000 N	Basic dynamic load rating, radial
$C_{0r}$	4.700 N	Basic static load rating, radial
$C_{ur}$	570 N	Fatigue load limit, radial
$n_G$	31.500 1/min	Limiting speed
$n_{gr}$	29.000 1/min	Reference speed