

★ K4X7X10-TV



Needle roller cage assembly

Schaeffler ID:
0006631906063

Needle roller cage assembly K...-TV, single row

★ Preferred product

Technical information

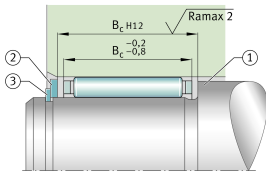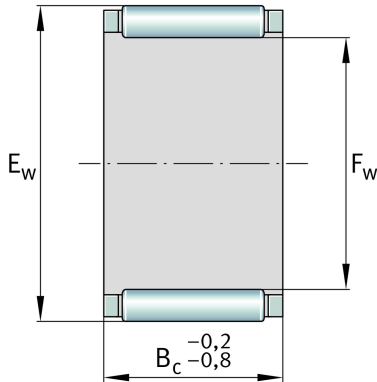

Temperature range

T_{min}	-20 °C	Operating temperature min.
T_{max}	120 °C	Operating temperature max.
	0,001 kg	Weight

Main Dimensions & Performance Data

F_w	4 mm	Inner diameter of needle roller complement
E_w	7 mm	Outside diameter of needle roller complement
B_c	10 mm	Width
C_r	2.330 N	Basic dynamic load rating, radial
C_{0r}	1.840 N	Basic static load rating, radial
C_{ur}	241 N	Fatigue load limit, radial
n_G	42.500 1/min	Limiting speed
n_{gr}	59.000 1/min	Reference speed