



IMAGE  
COMING SOON




## ★ NKIA59/22-XL

Needle roller/angular contact ball bearing

Schaeffler ID:  
0504213010000

★ Preferred product

### Technical information

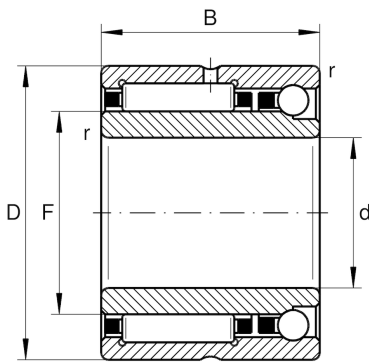

#### Main Dimensions & Performance Data

d	22 mm	Bore diameter
D	39 mm	Outside diameter
B	23 mm	Width
$C_r$	26.000 N	Basic dynamic load rating, radial
$C_{0r}$	29.500 N	Basic static load rating, radial
$C_a$	5.300 N	Basic dynamic load rating, axial
$C_{0a}$	8.600 N	Basic static load rating, axial
$C_{ur}$	5.400 N	Fatigue limit load, radial
$C_{ur}$	5.400 N	Fatigue load limit, radial
$C_{ua}$	395 N	Fatigue load limit, axial
$n_G$	16.100 1/min	Limiting speed
$n_{gr}$	12.000 1/min	Reference speed
	0,001 kg	Weight

#### Dimensions

F	28 mm	Raceway diameter inner ring
$r_{min}$	0,3 mm	Minimum chamfer dimension