



K75X83X40-ZW

Needle roller cage assembly

Schaeffler ID:
0000015626063

Needle roller cage assembly K..-ZW, two-row

Technical information

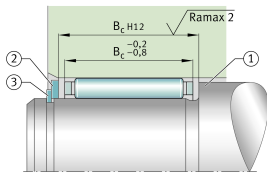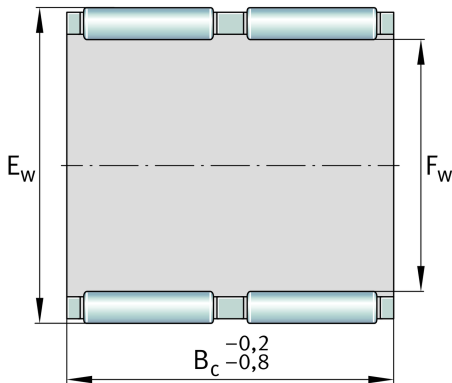

Temperature range

T_{min}	-30 °C	Operating temperature min.
T_{max}	140 °C	Operating temperature max.
	0,214 kg	Weight

Main Dimensions & Performance Data

F_w	75 mm	Inner diameter of needle roller complement
E_w	83 mm	Outside diameter of needle roller complement
B_c	40 mm	Width
C_r	73.000 N	Basic dynamic load rating, radial
C_{0r}	177.000 N	Basic static load rating, radial
C_{ur}	25.500 N	Fatigue load limit, radial
n_G	6.200 1/min	Limiting speed
n_{gr}	3.900 1/min	Reference speed